


[All Products](#) / [Lights and Illumination](#) / [Machine Vision Lighting](#) / [Spot Lights](#)

Advanced Illumination MicroBrite Compact Spot Lights See

More by [Advanced Illumination](#)

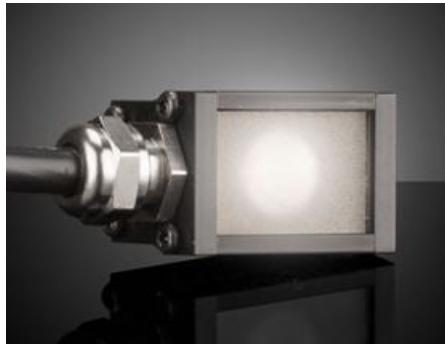

- Light Output up to 15,000 Lux
- Rectangular Housing with Small Footprint
- [MicroBrite High Intensity Spot Lights](#) Also Available
- Optional Manual Intensity Adjustments ([#86-887](#) and [#89-555](#)) Recommended

Common Specifications

General

LED Lifetime (hours):	50000	Type of Illumination:	LED Illuminator
Note:	Optional Manual Intensity Adjustment #86-887 and #89-555 are Available	Manufacturer:	Advanced Illumination
Geometry:	Spot Light	Illumination Mode:	Constant

Physical & Mechanical Properties

Dimensions (mm):	31.8 x 20.5 x 20.5	Weight (g):	24
-------------------------	--------------------	--------------------	----

Hardware & Interface Connectivity

Connector:	Flying Leads	Power Supply:	Power Supply Required and Sold Separately: USA: #66-855 Europe: #66-855 Japan: #89-513 Korea: #33-773 China: #66-855
Length of Cable (m):	2		

Environmental & Durability Factors

Operating Temperature (°C):	0 to +60
------------------------------------	----------

Technical Information

Products

Dimensions (mm)	Color	Wavelength (nm)	Stock Number	Price	Buy
31.8 x 20.5 x 20.5	White	-	#18-581	S\$560.00	3 In Stock
31.8 x 20.5 x 20.5	UV	365	#18-586	S\$560.00	1 In Stock
31.8 x 20.5 x 20.5	Blue	470	#18-583	S\$560.00	2 In Stock
31.8 x 20.5 x 20.5	Green	530	#18-584	S\$560.00	1 In Stock
31.8 x 20.5 x 20.5	Red	625	#18-582	S\$560.00	2 In Stock
31.8 x 20.5 x 20.5	IR	850	#18-585	S\$560.00	Contact Us
31.8 x 20.5 x 20.5	IR	940	#18-587	S\$560.00	1 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com