

[All Products](#) /
 [Optics](#) /
 [Optical Mirrors](#) /
 [Flat Mirrors](#) /
 [Precision Polished Metal Coatings](#)

TECHSPEC® $\lambda/20$ Fused Silica Right Angle Mirrors



- Precision Fused Silica Substrates for Increased Thermal Stability
- Ideal for System Alignment
- Enhanced Aluminum, Protected Gold, and Protected Silver Coatings Available

Common Specifications

Physical & Mechanical Properties

Dimensional Tolerance (mm):	+0.00/-0.10	Bevel:	Protective as needed
Optical Properties			
Surface Flatness (P-V):	$\lambda/20$	Substrate:	Fused Silica (Corning 7980)
Surface Quality:	20-10	Coating Type:	Metal
Angle Tolerance (arcsec):	± 15		

Technical Information


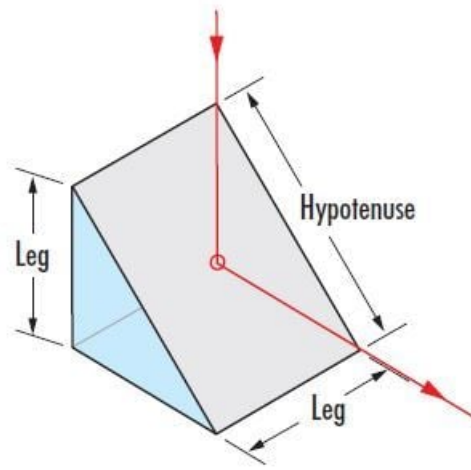


Image above shows light reflecting off the coated hypotenuse.

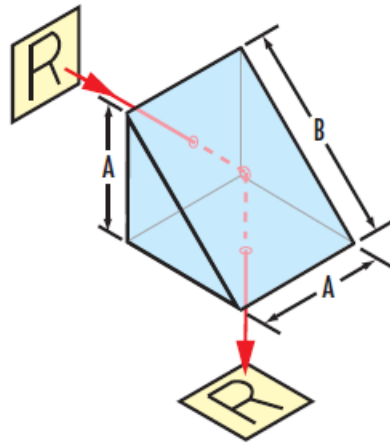

Products

Surface Flatness (P-V)	Length of Legs (mm)	Coating Specification	Coating	Stock Number	Price	Buy
$\lambda/20$	5.00	$R_{avg} > 95\%$ @ 450 - 650nm	Enhanced Aluminum (450-650nm)	#22-545	S\$271.82 Volume Pricing	15 In Stock
$\lambda/20$	10.00	$R_{avg} > 95\%$ @ 450 - 650nm	Enhanced Aluminum (450-650nm)	#22-546	S\$295.71 Volume Pricing	Contact Us
$\lambda/20$	12.50	$R_{avg} > 95\%$ @ 450 - 650nm	Enhanced Aluminum (450-650nm)	#22-547	S\$303.18 Volume Pricing	3 In Stock
$\lambda/20$	15.00	$R_{avg} > 95\%$ @ 450 - 650nm	Enhanced Aluminum (450-650nm)	#22-548	S\$325.58 Volume Pricing	6 In Stock
$\lambda/20$	20.00	$R_{avg} > 95\%$ @ 450 - 650nm	Enhanced Aluminum (450-650nm)	#22-549	S\$349.48 Volume Pricing	4 In Stock
$\lambda/20$	25.00	$R_{avg} > 95\%$ @ 450 - 650nm	Enhanced Aluminum (450-650nm)	#22-550	S\$364.41 Volume Pricing	Contact Us
$\lambda/20$	5.00	$R_{avg} > 98\%$ @ 450 - 800nm $R_{avg} > 98.5\%$ @ 2000 - 10,000nm	Protected Silver (450-10000nm)	#22-551	S\$286.75 Volume Pricing	9 In Stock
$\lambda/20$	10.00	$R_{avg} > 98\%$ @ 450 - 800nm $R_{avg} > 98.5\%$ @ 2000 - 10,000nm	Protected Silver (450-10000nm)	#22-552	S\$310.65 Volume Pricing	3 In Stock
$\lambda/20$	12.50	$R_{avg} > 98\%$ @ 450 - 800nm $R_{avg} > 98.5\%$ @ 2000 - 10,000nm	Protected Silver (450-10000nm)	#22-553	S\$318.12 Volume Pricing	Contact Us

$\lambda/20$	15.00	$R_{avg} > 98\% @$ 450 - 800nm $R_{avg} > 98.5\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	#22-554	S\$342.01 Volume Pricing	5 In Stock
$\lambda/20$	20.00	$R_{avg} > 98\% @$ 450 - 800nm $R_{avg} > 98.5\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	#22-555	S\$364.41 Volume Pricing	8 In Stock
$\lambda/20$	25.00	$R_{avg} > 98\% @$ 450 - 800nm $R_{avg} > 98.5\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	#22-556	S\$403.25 Volume Pricing	13 In Stock
$\lambda/20$	5.00	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700-10000nm)	#22-557	S\$310.65 Volume Pricing	12 In Stock
$\lambda/20$	10.00	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700-10000nm)	#22-558	S\$342.01 Volume Pricing	Contact Us
$\lambda/20$	12.50	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700-10000nm)	#22-559	S\$349.48 Volume Pricing	Contact Us
$\lambda/20$	15.00	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700-10000nm)	#22-560	S\$388.31 Volume Pricing	14 In Stock
$\lambda/20$	20.00	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700-10000nm)	#22-561	S\$412.21 Volume Pricing	15 In Stock
$\lambda/20$	25.00	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700-10000nm)	#22-562	S\$434.61 Volume Pricing	11 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com