


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Concave \(PCV\) Lenses](#)

TECHSPEC® YAG-BBAR Coated Plano-Concave (PCV) Lenses

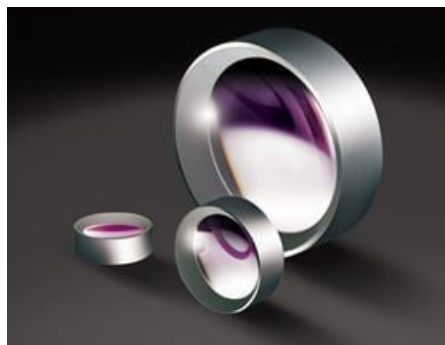

- Negative Focal Lengths for Beam Expansion or Light Projection Applications
- Optimized for $R < 0.25\%$ at both 532nm and 1064nm
- AR Coated to Provide $< 1.0\%$ Reflectance per Surface for 500 - 1100nm
- Various Coating Options: [Uncoated](#), [VIS-EXT](#), [MgF₂](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [NIR II](#), and [1064nm V-Coat](#)

Common Specifications

Physical & Mechanical Properties

Bevel: Protective as needed

Optical Properties

Coating: YAG-BBAR (500-1100nm)

Wavelength Range (nm):	500 - 1100	Focal Length Specification Wavelength (nm):	587.6
Focal Length Tolerance (%):	± 1	Damage Threshold, By Design:	5 J/cm ² @ 532nm, 10ns
Power (P-V) @ 632.8nm:	1.5 λ	Irregularity (P-V) @ 632.8nm:	$\lambda/4$

Technical Information

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
3.00	-6.00	-6.56	YAG-BBAR (500- 1100nm)	N-SF11	#21-299	S\$106.04 Volume Pricing	10 In Stock
3.00	-9.00	-9.56	YAG-BBAR (500- 1100nm)	N-SF11	#21-300	S\$106.04 Volume Pricing	5 In Stock
6.00	-6.00	-6.84	YAG-BBAR (500- 1100nm)	N-SF11	#21-301	S\$64.22 Volume Pricing	Contact Us
6.00	-9.00	-9.84	YAG-BBAR (500- 1100nm)	N-SF11	#21-302	S\$64.22 Volume Pricing	9 In Stock
6.00	-12.00	-12.99	YAG-BBAR (500- 1100nm)	N-BK7	#21-303	S\$64.22 Volume Pricing	3 In Stock
6.00	-15.00	-16.32	YAG-BBAR (500- 1100nm)	N-BK7	#21-304	S\$64.22 Volume Pricing	4 In Stock
6.00	-18.00	-19.32	YAG-BBAR (500- 1100nm)	N-BK7	#21-305	S\$64.22 Volume Pricing	7 In Stock
9.00	-9.00	-10.21	YAG-BBAR (500- 1100nm)	N-SF11	#21-306	S\$65.71 Volume Pricing	7 In Stock
9.00	-12.00	-13.26	YAG-BBAR (500- 1100nm)	N-SF11	#21-307	S\$65.71 Volume Pricing	15 In Stock
9.00	-18.00	-19.26	YAG-BBAR (500- 1100nm)	N-SF11	#21-308	S\$65.71 Volume Pricing	14 In Stock
9.00	-27.00	-28.68	YAG-BBAR (500- 1100nm)	N-SF11	#21-309	S\$65.71 Volume Pricing	20+ In Stock
12.00	-12.00	-13.23	YAG-BBAR (500- 1100nm)	N-SF11	#21-310	S\$68.70 Volume Pricing	Contact Us

12.00	-15.00	-16.68	YAG-BBAR (500-1100nm)	N-SF11	#21-311	S\$68.70 Volume Pricing	2 In Stock
12.00	-18.00	-19.95	YAG-BBAR (500-1100nm)	N-SF11	#21-312	S\$68.70 Volume Pricing	2 In Stock
12.00	-24.00	-26.32	YAG-BBAR (500-1100nm)	N-BK7	#21-313	S\$68.70 Volume Pricing	10 In Stock
12.00	-48.00	-50.31	YAG-BBAR (500-1100nm)	N-BK7	#21-314	S\$68.70 Volume Pricing	6 In Stock
20.00	-30.00	-31.96	YAG-BBAR (500-1100nm)	N-SF11	#21-315	S\$72.44 Volume Pricing	3 In Stock
20.00	-40.00	-42.31	YAG-BBAR (500-1100nm)	N-BK7	#21-316	S\$72.44 Volume Pricing	1 In Stock
20.00	-50.00	-52.31	YAG-BBAR (500-1100nm)	N-BK7	#21-317	S\$72.44 Volume Pricing	1 In Stock
20.00	-	-	YAG-BBAR (500-1100nm)	N-BK7	#21-335	S\$72.44 Volume Pricing	5 In Stock
25.00	-25.00	-26.96	YAG-BBAR (500-1100nm)	N-SF11	#21-318	S\$76.17 Volume Pricing	15 In Stock
25.00	-35.00	-36.96	YAG-BBAR (500-1100nm)	N-SF11	#21-319	S\$76.17 Volume Pricing	10 In Stock
25.00	-50.00	-52.31	YAG-BBAR (500-1100nm)	N-BK7	#21-320	S\$76.17 Volume Pricing	7 In Stock
25.00	-	-	YAG-BBAR (500-1100nm)	N-BK7	#21-321	S\$76.17 Volume Pricing	4 In Stock
50.00	-	-	YAG-BBAR (500-1100nm)	N-BK7	#21-322	S\$111.26 Volume Pricing	3 In Stock
50.00	-	-	YAG-BBAR (500-1100nm)	N-BK7	#21-323	S\$111.26 Volume Pricing	1 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com