


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [Optical Diffusers](#)

Wide Angle Diffusers

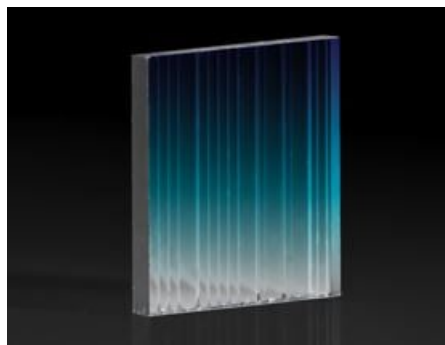

- 25 and 125° Diffusing Angles Available
- 90% Transmission Efficiency
- Eye-Safe ROE, No Zero-Order and No Hot Spot

Common Specifications

General

Note:

Recommended $M^2 > 10$ and beam size $> 2.5\text{mm FW/e}^2$ for best homogeneity and steep slopes

Physical & Mechanical Properties

Clear Aperture CA (mm): 4.5 x 4.5

Dimensions (mm): 5.00 x 5.00 ± 0.1

Thickness (mm): 0.50 ± 0.05

Optical Properties

Coating: Uncoated

Transmission (%): 90

Design Wavelength DWL (nm): 1064

Technical Information

Products

Title	Stock Number	Price	Buy
25° Diffusing Angle, 5mm Sq., Wide Angle Diffuser	#23-876	S\$458.50 Volume Pricing	5 In Stock
125° Diffusing Angle, 5mm Sq., Wide Angle Diffuser	#23-877	S\$458.50 Volume Pricing	4 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com