


[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Flat Mirrors](#) / [Laser Mirrors](#)

TECHSPEC® Polarization Maintaining Mirrors

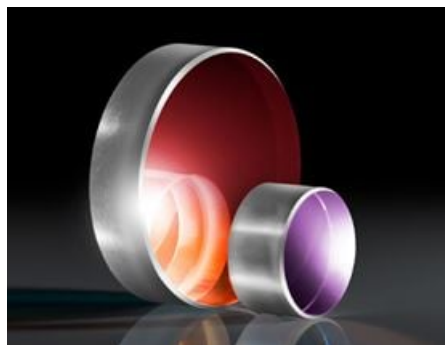

- Preserves Incident Circular Polarization at 45° AOI
- Up To 99.9% Reflection at 532 or 1064nm, and 80% at 650nm for Alignment
- 12.7, 25.4, and 50.8mm Designs Available

Common Specifications

Physical & Mechanical Properties

Clear Aperture (%):	90
---------------------	----

Optical Properties


Substrate:	Fused Silica
------------	------------------------------

Angle of Incidence (°):	45
-------------------------	----

Surface Flatness (P-V):	$\lambda/8$
-------------------------	-------------

Technical Information

Theory of Operation

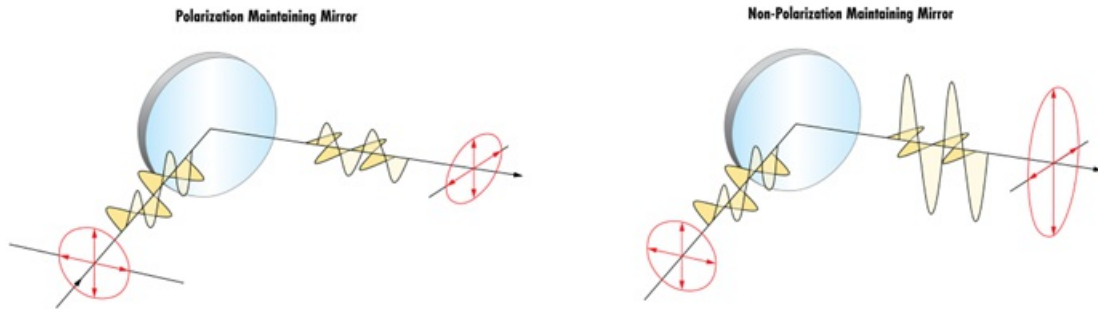

Products

Title	Stock Number	Price	Buy
Polarization Maintaining Mirror, 532nm, 45° AOI, 12.7mm Dia., 6.35mm Thick	#26-868	S\$316.40 Volume Pricing	6 In Stock
Polarization Maintaining Mirror, 532nm, 45° AOI, 25.4mm Dia., 6.35mm Thick	#26-869	S\$396.20 Volume Pricing	11 In Stock
Polarization Maintaining Mirror, 532nm, 45° AOI, 50.8mm Dia., 9.53mm Thick	#26-870	S\$625.80 Volume Pricing	Contact Us
Polarization Maintaining Mirror, 1064nm, 45° AOI, 12.7mm Dia., 6.35mm Thick	#26-871	S\$316.40 Volume Pricing	7 In Stock
Polarization Maintaining Mirror, 1064nm, 45° AOI, 25.4mm Dia., 6.35mm Thick	#26-872	S\$396.20 Volume Pricing	20+ In Stock
Polarization Maintaining Mirror, 1064nm, 45° AOI, 50.8mm Dia., 9.53mm Thick	#26-873	S\$625.80 Volume Pricing	2 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com