


[All Products](#) / [Cameras](#) / [Gigabit Ethernet Cameras](#)

Teledyne DALSA Linea GigE Line Scan Cameras [See More by Teledyne DALSA](#)

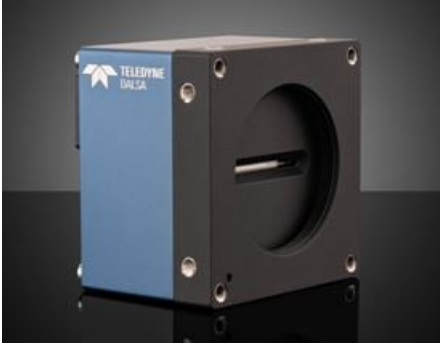

- Line Rates from 13 – 52kHz
- 2k, 4k, or 8k Resolution Options Available
- Simple Integration with Gigabit Ethernet Connectivity
- Teledyne TurboDrive™ Enabled
- Monochrome and Color Options Available

Common Specifications

General			
Manufacturer:	Teledyne DALSA	Camera Series:	LINEA™
Physical & Mechanical Properties			
Housing:	Full		
Sensor			
Pixel Size, H x V (µm):	7.04 x 7.04		
Type of Sensor:	DALSA Line Scan CMOS	Dynamic Range (dB):	>60.00
Machine Vision Standard:	GigE Vision v1.2		
Hardware & Interface Connectivity			
Interface:	GigE		
Connector:	GigE, RJ45 with Screw Locks	Power Supply:	+12 to +24V DC HD15 Connector
Interface Port Orientation:	Back Panel	GPIO Connector Type:	HD15 (High Density)
Environmental & Durability Factors			
Operating Temperature (°C):	0 to +65	Storage Temperature (°C):	(Front Plate)

Technical Information

Products

Type	Model Number	Resolution (Pixels)	Mount	Stock Number	Price	Buy
Monochrome Camera	LA-GM-02K08A-00-R	2048.00	M42-Mount	#71-779	S\$1,820.00	Contact Us
Monochrome Camera	LA-GM-04K08A-00-R	4096.00	M42-Mount	#71-780	S\$2,282.00	Contact Us
Monochrome Camera	LA-GM-08K08A-00-R	8192.00	M72 x 0.75	#71-781	S\$3,178.00	1 In Stock
Color Camera	LA-GC-02K05B-00-R	2048 x 2	M42-Mount	#71-782	S\$2,366.00	1 In Stock
Color Camera	LA-GC-04K05B-00-R	4096 x 2	M42-Mount	#71-783	S\$2,968.00	Contact Us



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com