


[All Products](#) / [Testing and Detection](#) / [Spectroscopy](#)

Wavelength References Fiber-Coupled Gas Cells

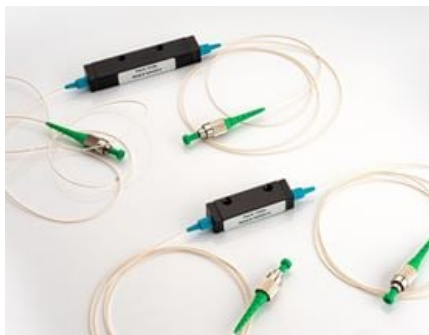

- Hydrogen Cyanide and Acetylene Gasses Available for Wavelength Coverage of 1510 to 1565nm
- FC and SC Fiber Connection Options with a Variety of Path Lengths Available
- NIST Traceable Reference Cells

Common Specifications

Optical Properties

Transmission (%):

>50

Technical Information

Products

Model Number	Fiber Connector Type	Wavelength Range (nm)	Type	Path Length (cm)	Stock Number	Price	Buy
HCN-13-H(5.5)-25-FCAPC	FC/APC	1525 - 1565	Hydrogen Cyanide (H ¹³ C ¹⁴ N)	5.5	#72-196	S\$973.00 Volume Pricing	1 In Stock
HCN-13-H(16.5)-25-FCAPC	FC/APC	1525 - 1565	Hydrogen Cyanide (H ¹³ C ¹⁴ N)	16.5	#72-200	S\$1,435.00 Volume Pricing	Contact Us
C2H2-12-H(3)-200-FCAPC	FC/APC	1510 - 1540	Acetylene (¹² C ₂ H ₂)	3	#72-204	S\$819.00 Volume Pricing	1 In Stock
C2H2-12-H(5.5)-50-FCAPC	FC/APC	1510 - 1540	Acetylene (¹² C ₂ H ₂)	5.5	#72-208	S\$903.00 Volume Pricing	Contact Us
HCN-13-H(5.5)-25-SCAPC	SC/APC	1525 - 1565	Hydrogen Cyanide (H ¹³ C ¹⁴ N)	5.5	#72-197	S\$973.00 Volume Pricing	1 In Stock
HCN-13-H(16.5)-25-SCAPC	SC/APC	1525 - 1565	Hydrogen Cyanide (H ¹³ C ¹⁴ N)	16.5	#72-201	S\$1,435.00 Volume Pricing	1 In Stock
C2H2-12-H(3)-200-SCAPC	SC/APC	1510 - 1540	Acetylene (¹² C ₂ H ₂)	3	#72-205	S\$819.00 Volume Pricing	1 In Stock
C2H2-12-H(5.5)-50-SCAPC	SC/APC	1510 - 1540	Acetylene (¹² C ₂ H ₂)	5.5	#72-209	S\$903.00 Volume Pricing	1 In Stock
HCN-13-H(5.5)-25-FCPC	FC/PC	1525 - 1565	Hydrogen Cyanide (H ¹³ C ¹⁴ N)	5.5	#72-198	S\$973.00 Volume Pricing	Contact Us

HCN-13- H(16.5)- 25- FCPC	FC/PC	1525 - 1565	Hydrogen Cyanide (H ¹³ C ¹⁴ N)	16.5	#72-202	S\$1,435.00 Volume Pricing	1 In Stock
C2H2- 12-H(3)- 200- FCPC	FC/PC	1510 - 1540	Acetylene (¹² C ₂ H ₂)	3	#72-206	S\$819.00 Volume Pricing	1 In Stock
C2H2- 12- H(5.5)- 50- FCPC	FC/PC	1510 - 1540	Acetylene (¹² C ₂ H ₂)	5.5	#72-210	S\$903.00 Volume Pricing	Contact Us
HCN-13- H(5.5)- 25- SCPC	SC/PC	1525 - 1565	Hydrogen Cyanide (H ¹³ C ¹⁴ N)	5.5	#72-199	S\$973.00 Volume Pricing	1 In Stock
HCN-13- H(16.5)- 25- SCPC	SC/PC	1525 - 1565	Hydrogen Cyanide (H ¹³ C ¹⁴ N)	16.5	#72-203	S\$1,435.00 Volume Pricing	1 In Stock
C2H2- 12-H(3)- 200- SCPC	SC/PC	1510 - 1540	Acetylene (¹² C ₂ H ₂)	3	#72-207	S\$819.00 Volume Pricing	1 In Stock
C2H2- 12- H(5.5)- 50- SCPC	SC/PC	1510 - 1540	Acetylene (¹² C ₂ H ₂)	5.5	#72-211	S\$903.00 Volume Pricing	1 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com