

[All Products](#) / [Lights and Illumination](#) / [Microscopy Lighting](#) / [Fiber Optic Illuminators](#)

SCHOTT KL Fiber Optic Light Sources

See More by [SCHOTT Optical Components](#)

- Maximum Light Intensity of 1100 Lumens
- Continuous Dimming from 0 - 100%
- Various Light Guide Options Available
- Ideal for Use with Stereo Microscopes

Common Specifications

General

Operating Lifetime (hours):	>50,000	Intensity Control Option:	Yes
Type of Illumination:	LED Illuminator	Manufacturer:	SCHOTT
Illumination Mode:	Constant		

Physical & Mechanical Properties

Dimensions (mm):	114L x 231W x 137H
-------------------------	--------------------

Optical Properties

Color:	White
---------------	-------

Hardware & Interface Connectivity


Input Voltage (V):	24 DC
---------------------------	-------

Power Supply:	Power Cord Required and Sold Separately: USA: #16-792 Europe: #18-492 Japan: #78-580 Korea: #16-792 China: #16-792 UK: #18-493 Switzerland: #18-494
----------------------	--

Environmental & Durability Factors

Color Temperature (K):	5600
-------------------------------	------

Technical Information

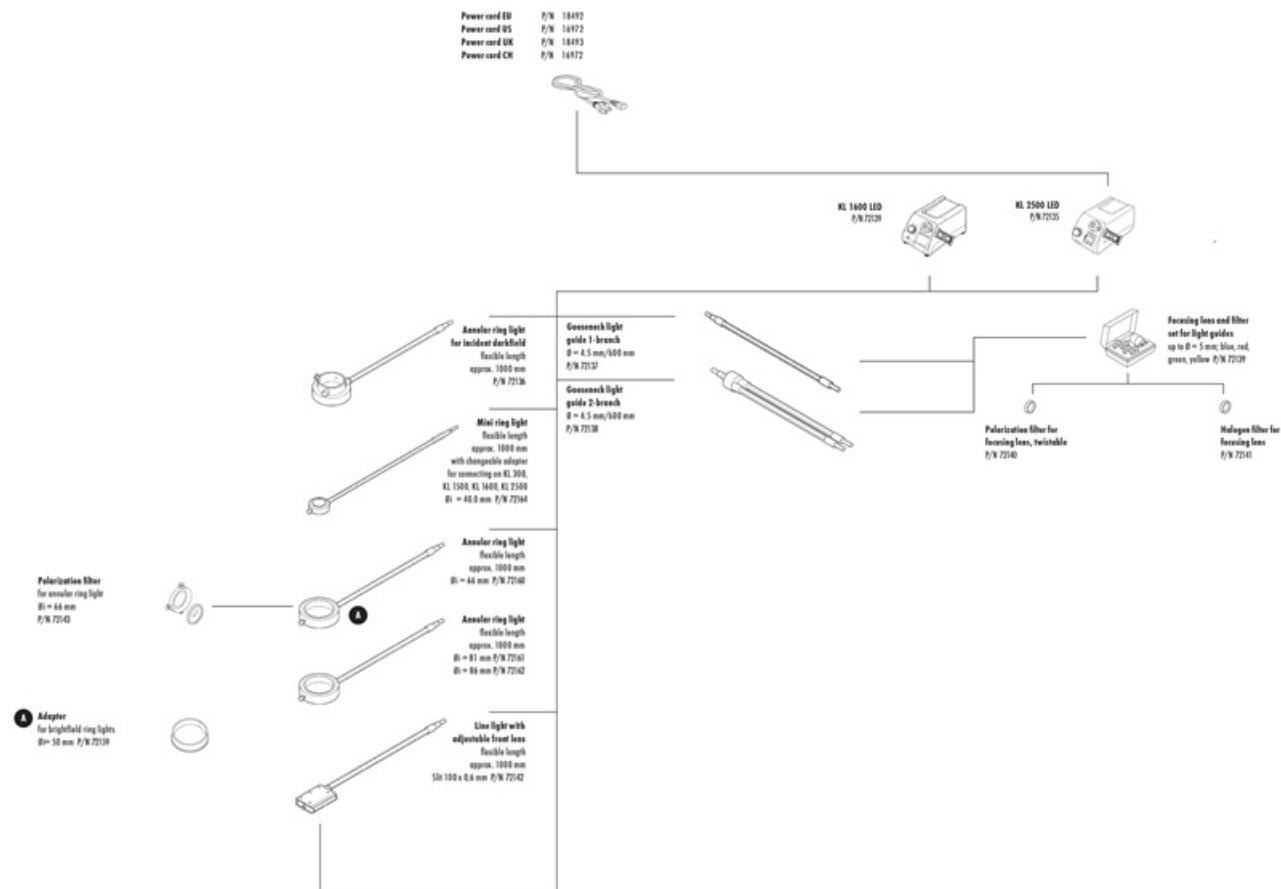

SCHOTT
glass made of ideas

Products

Title	Stock Number	Price	Buy
Schott KL 1600 LED Light Source	#72-134	S\$1,435.00	2 In Stock
Schott KL 2500 LED Light Source	#72-135	S\$2,142.00	2 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com