

[All Products](#) /
 [Optics](#) /
 [Optical Mirrors](#) /
 [Focusing \(Concave\) Mirrors](#)

TECHSPEC® Broadband Dielectric Spherical Mirrors






- Ideal for Multispectral Focusing Applications
- Average Reflectivity >99% Over Broad UV, Visible, and NIR Wavelengths
- Multiple Sizes Available


Common Specifications

Physical & Mechanical Properties

Back Surface: Ground	Edge Thickness Tolerance (%): +0.0/-15
Optical Properties	
Coating Type: Dielectric	Focal Length Tolerance (%): ±2
Surface Accuracy: $\lambda/4$	Surface Quality: 60-40

Technical Information

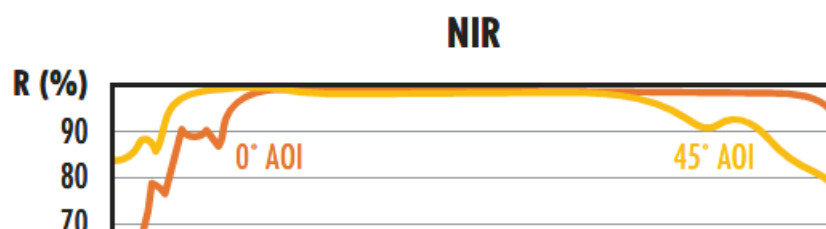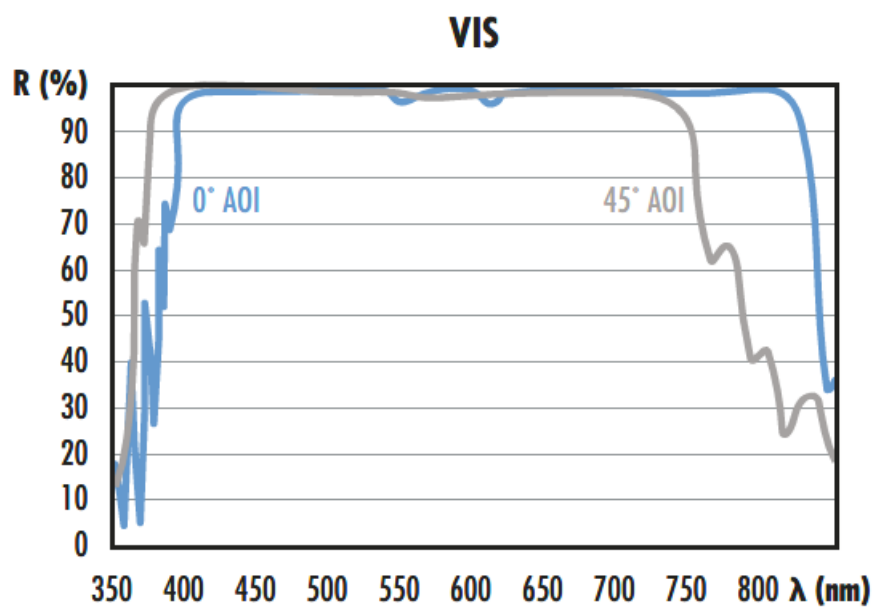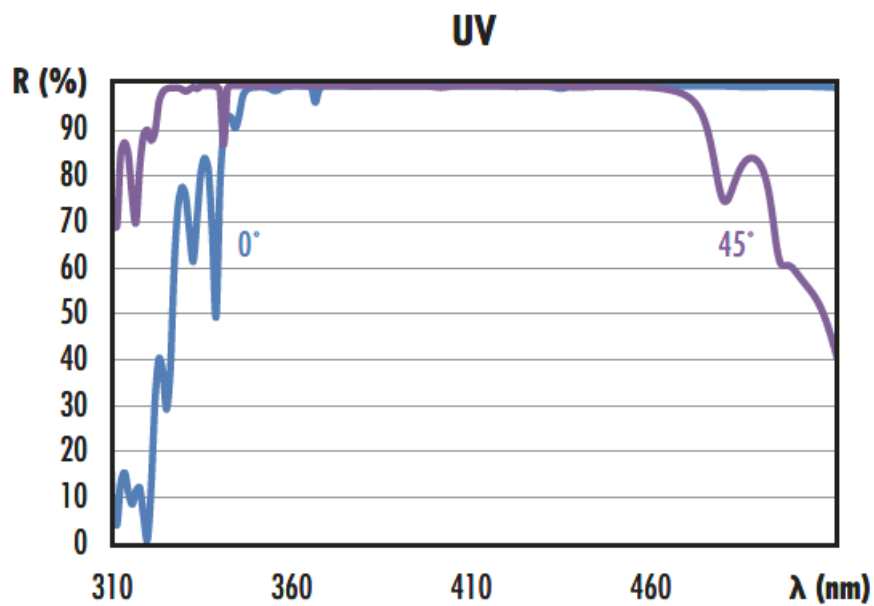

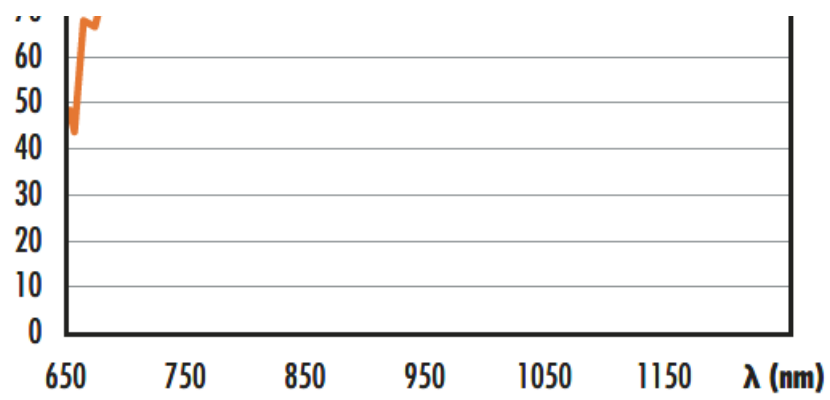

Products

Dia. (mm)	Wavelength Range (nm)	EFL (mm)	ET (mm)	Stock Number	Price	Buy
25.40	320 - 450	25.40	6.35	#72-960	S\$253.90 Volume Pricing	9 In Stock
25.40	320 - 450	50.80	6.35	#72-961	S\$253.90 Volume Pricing	14 In Stock
25.40	320 - 450	76.20	6.35	#72-962	S\$253.90 Volume Pricing	8 In Stock
25.40	320 - 450	101.60	6.35	#72-963	S\$253.90 Volume Pricing	9 In Stock
25.40	320 - 450	152.40	6.35	#72-964	S\$253.90 Volume Pricing	8 In Stock
25.40	320 - 450	203.20	6.35	#72-965	S\$253.90 Volume Pricing	Contact Us
50.80	320 - 450	50.80	12.70	#72-966	S\$410.71 Volume Pricing	10 In Stock
50.80	320 - 450	101.60	12.70	#72-967	S\$410.71 Volume Pricing	10 In Stock
50.80	320 - 450	152.40	12.70	#72-968	S\$410.71 Volume Pricing	4 In Stock
50.80	320 - 450	203.20	12.70	#72-969	S\$410.71 Volume Pricing	7 In Stock
50.80	320 - 450	304.80	12.70	#72-970	S\$410.71 Volume Pricing	4 In Stock
50.80	320 - 450	508.00	12.70	#72-971	S\$410.71 Volume Pricing	4 In Stock
50.80	320 - 450	1,016.00	12.70	#72-972	S\$410.71 Volume Pricing	5 In Stock
76.20	320 - 450	76.20	12.70	#72-973	S\$634.74 Volume Pricing	3 In Stock
76.20	320 - 450	152.40	12.70	#72-974	S\$634.74 Volume Pricing	3 In Stock
76.20	320 - 450	203.20	12.70	#72-975	S\$634.74 Volume Pricing	3 In Stock
76.20	320 - 450	304.80	12.70	#72-976	S\$634.74 Volume Pricing	3 In Stock

76.20	320 - 450	457.20	12.70	#72-977	S\$634.74 Volume Pricing	3 In Stock
76.20	320 - 450	762.00	12.70	#72-978	S\$634.74 Volume Pricing	3 In Stock
152.40	320 - 450	609.60	25.40	#72-979	S\$1,792.20 Volume Pricing	1 In Stock
25.40	400 - 750	25.40	6.35	#72-980	S\$224.03 Volume Pricing	13 In Stock
25.40	400 - 750	50.80	6.35	#72-981	S\$224.03 Volume Pricing	12 In Stock
25.40	400 - 750	76.20	6.35	#72-982	S\$224.03 Volume Pricing	14 In Stock
25.40	400 - 750	101.60	6.35	#72-983	S\$224.03 Volume Pricing	14 In Stock
25.40	400 - 750	152.40	6.35	#72-984	S\$224.03 Volume Pricing	16 In Stock
25.40	400 - 750	203.20	6.35	#72-985	S\$224.03 Volume Pricing	14 In Stock
50.80	400 - 750	50.80	12.70	#72-986	S\$373.38 Volume Pricing	5 In Stock
50.80	400 - 750	101.60	12.70	#72-987	S\$373.38 Volume Pricing	5 In Stock
50.80	400 - 750	152.40	12.70	#72-988	S\$373.38 Volume Pricing	9 In Stock
50.80	400 - 750	203.20	12.70	#72-989	S\$373.38 Volume Pricing	10 In Stock
50.80	400 - 750	304.80	12.70	#72-990	S\$373.38 Volume Pricing	11 In Stock
50.80	400 - 750	508.00	12.70	#72-991	S\$373.38 Volume Pricing	9 In Stock
50.80	400 - 750	1,016.00	12.70	#72-992	S\$373.38 Volume Pricing	4 In Stock
76.20	400 - 750	76.20	12.70	#72-993	S\$589.93 Volume Pricing	3 In Stock
76.20	400 - 750	152.40	12.70	#72-994	S\$589.93 Volume Pricing	Contact Us
76.20	400 - 750	203.20	12.70	#72-995	S\$589.93 Volume Pricing	1 In Stock
76.20	400 - 750	304.80	12.70	#72-996	S\$589.93 Volume Pricing	3 In Stock

76.20	400 - 750	457.20	12.70	#72-997	S\$589.93 Volume Pricing	1 In Stock
76.20	400 - 750	762.00	12.70	#72-998	S\$589.93 Volume Pricing	2 In Stock
152.40	400 - 750	609.60	25.40	#72-999	S\$1,680.19 Volume Pricing	1 In Stock
25.40	750 - 1100	25.40	6.35	#73-000	S\$224.03 Volume Pricing	12 In Stock
25.40	750 - 1100	50.80	6.35	#73-001	S\$224.03 Volume Pricing	7 In Stock
25.40	750 - 1100	76.20	6.35	#73-002	S\$224.03 Volume Pricing	8 In Stock
25.40	750 - 1100	101.60	6.35	#73-003	S\$224.03 Volume Pricing	5 In Stock
25.40	750 - 1100	152.40	6.35	#73-006	S\$224.03 Volume Pricing	11 In Stock
25.40	750 - 1100	203.20	6.35	#73-007	S\$224.03 Volume Pricing	Contact Us
50.80	750 - 1100	50.80	12.70	#73-008	S\$373.38 Volume Pricing	5 In Stock
50.80	750 - 1100	101.60	12.70	#73-009	S\$373.38 Volume Pricing	7 In Stock
50.80	750 - 1100	152.40	12.70	#73-010	S\$373.38 Volume Pricing	4 In Stock
50.80	750 - 1100	203.20	12.70	#73-011	S\$373.38 Volume Pricing	5 In Stock
50.80	750 - 1100	304.80	12.70	#73-015	S\$373.38 Volume Pricing	3 In Stock
50.80	750 - 1100	508.00	12.70	#73-020	S\$373.38 Volume Pricing	5 In Stock
50.80	750 - 1100	1,016.00	12.70	#73-021	S\$373.38 Volume Pricing	5 In Stock
76.20	750 - 1100	76.20	12.70	#73-024	S\$589.93 Volume Pricing	5 In Stock
76.20	750 - 1100	152.40	12.70	#73-025	S\$589.93 Volume Pricing	2 In Stock
76.20	750 - 1100	203.20	12.70	#73-026	S\$589.93 Volume Pricing	2 In Stock
76.20	750 - 1100	304.80	12.70	#73-027	S\$589.93 Volume Pricing	3 In Stock

76.20	750 - 1100	457.20	12.70	#73-030	S\$589.93 Volume Pricing	2 In Stock
76.20	750 - 1100	762.00	12.70	#73-034	S\$589.93 Volume Pricing	3 In Stock
152.40	750 - 1100	609.60	25.40	#73-036	S\$1,680.19 Volume Pricing	Contact Us



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com